

Special



Image for illustrative purpose only

Summary

[Request a quote](#)

SE series

Size

0S

Series

S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-0s-200-npsn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Insulator P: PEHD

Form & Material

Shell style / Model id BRE - Cap for receptacle

Housing material Brass (nickel plated [SAE AMS QQ N 290]) collet and crimping tube, brass (chrome plated [SAE AMS 2460]) collet nut

Keying No keying

Colour Grey

Weight 3.43 g

Environment

Technical domain Audio Video, Energy and Industrial, Semiconductor, Test and Measurement

Environmental sealing (IP rating) IP50

Temperature range -50°C / +135°C

Climatic Category 55/175/21


Humidity (max) <=95% [at 60 deg C /140 F]

Shock Resistance 100 g [6 ms]

Vibration 15 g [10 Hz - 2000 Hz]

Salt Spray Corrosion >144 hr

Drawings

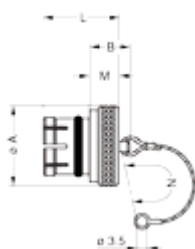

No keying

Dimensions

	A	B	L	M	N
mm.	10	9.5	10.5	4.5	85
in.	0.39	0.37	0.41	0.18	3.35

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-0s-200-npsn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.