



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Size	2K
Series	K - Outdoor keyed

Technical details


Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Keying	No keying
Colour	Grey
Weight	27.75 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Drawings

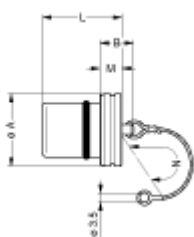

No keying

Dimensions

	A	B	L	M	N
mm.	20.5	14	24	8	85
in.	0.81	0.55	0.94	0.31	3.35

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bre-2k-200-cas.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.