



## Summary

[Request a quote](#)

[Catalog](#)

|        |                           |
|--------|---------------------------|
| Size   | 2S                        |
| Series | S - Indoor Stepped Insert |

## Technical details

### Form & Material

|                        |  |
|------------------------|--|
| Shell style / Model id | BRE - Cap for receptacle   |
| Housing material       | Brass (nickel plated [SAE AMS QQ N 290]) collet and crimping tube, brass (chrome plated [SAE AMS 2460]) collet nut |
| Keying                 | No keying  |
| Weight                 | 12.07 g  |


[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/bre-2s-200-nas.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-2s-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Environment

|                                      |   |
|--------------------------------------|---|
| Technical domain                     | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental protection (IP rating) | IP61  |
| Minimal temperature                  | -50°C / +135°C  |
| Climatical Category                  | 50/175/21   |
| Humidity (max)                       | <=95% [at 60 deg C /140 F]  |
| Shielding (min)                      | 75 dB (10 MHz)  |
| Shielding (min)                      | 40 dB (1 GHz)   |
| Shock Resistance                     | 100 g [ 6 ms]   |
| Vibration                            | 15 g [10 Hz - 2000 Hz]  |
| Salt Spray Corrosion                 | >144 hr   |

## Drawings

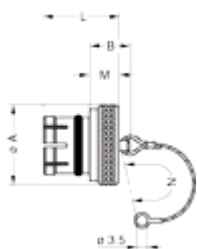

No keying

## Dimensions

|     | <b>A</b> | <b>B</b> | <b>L</b> | <b>M</b> | <b>N</b> |
|-----|----------|----------|----------|----------|----------|
| mm. | 18       | 12       | 14       | 6        | 85       |
| in. | 0.71     | 0.47     | 0.55     | 0.24     | 3.35     |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/bre-2s-200-nas.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/bre-2s-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.