



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

[Catalog](#)

---

Locking system

Threaded

---

Size

2V

[https://www.lemo.com/int\\_en/bre-2v-200-nas.html](https://www.lemo.com/int_en/bre-2v-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	No keying
Colour	Grey

## Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +200°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

## Drawings

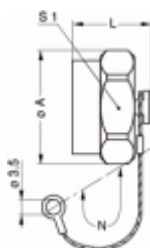

No keying

## Dimensions

	<b>A</b>	<b>L</b>	<b>N</b>	<b>S1</b>
mm.	23.5	14.7	85	22
in.	0.93	0.58	3.35	0.87

[https://www.lemo.com/int\\_en/bre-2v-200-nas.html](https://www.lemo.com/int_en/bre-2v-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.