



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	2V

https://www.lemo.com/int_en/bre-2v-200-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	No keying
Colour	Grey
Weight	22.58 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars
Salt Spray Corrosion	>144 hr

Drawings

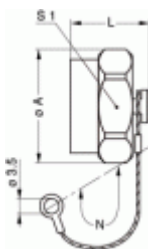

No keying

Dimensions

	A	L	N	S1
mm.	23.5	14.7	85	22
in.	0.93	0.58	3.35	0.87

https://www.lemo.com/int_en/bre-2v-200-naz.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.