



## Summary

[Request a quote](#)

---

[Catalog](#)

---

|      |    |
|------|----|
| Size | 3K |
|------|----|

---

|        |                   |
|--------|-------------------|
| Series | K - Outdoor keyed |
|--------|-------------------|

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bre-3k-200-sas.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bre-3k-200-sas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

|                        |  |
|------------------------|--|
| Shell style / Model id | BRE - Cap for receptacle   |
| Housing material       | Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Keying                 | No keying  |
| Colour                 | Grey   |
| Weight                 | 39.85 g  |

## Environment

|                                   |   |
|-----------------------------------|---|
| Technical domain                  | Audio Video, Energy and Industrial, Medical, Test and Measurement |
| Environmental sealing (IP rating) | IP68  |
| Temperature range                 | -50°C / +135°C  |
| Climatical Category               | 50/175/21   |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]  |
| Shielding (min)                   | 95 dB (10 MHz)  |
| Shielding (min)                   | 80 dB (1 GHz)   |
| Shock Resistance                  | 100 g [ 6 ms]   |
| Vibration                         | 15 g [10 Hz - 2000 Hz]  |

## Drawings

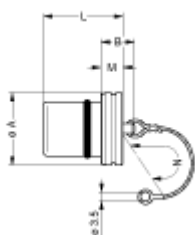

No keying

## Dimensions

|     | A    | B    | L   | M    | N    |
|-----|------|------|-----|------|------|
| mm. | 24   | 14   | 28  | 8    | 120  |
| in. | 0.94 | 0.55 | 1.1 | 0.31 | 4.72 |

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bre-3k-200-sas.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bre-3k-200-sas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.