



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

---

[Catalog](#)

---

Size

3T

---

Series

T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bre-3t-200-caz.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bre-3t-200-caz.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRE - Blanking cap for sockets
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	No keying
Colour	Grey
Weight	17.43 g

## Environment

Environmental sealing (IP rating)	IP68
Temperature range	-55°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

## Drawings

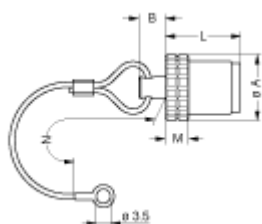

No keying

## Dimensions

	A	B	L	M	N
mm.	18.8	6.4	21.2	6.4	120
in.	0.74	0.25	0.83	0.25	4.72

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/bre-3t-200-caz.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/bre-3t-200-caz.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.