



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[V series en](#)

---

Locking system	Threaded
Size	3V

---

[https://www.lemo.com/int\\_en/bre-3v-200-nas.html](https://www.lemo.com/int_en/bre-3v-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	No keying
Colour	Grey
Weight	32.82 g

## Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatic Category	20/200/21
Pressure	30 bars
Salt Spray Corrosion	>144 hr

## Drawings

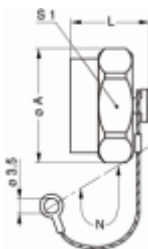

No keying

## Dimensions

	A	L	N	S1
mm.	27.8	14.7	120	26
in.	1.09	0.58	4.72	1.02

[https://www.lemo.com/int\\_en/bre-3v-200-nas.html](https://www.lemo.com/int_en/bre-3v-200-nas.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.