



Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Locking system	Threaded
Size	3V

Technical details


Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	Circular, female
Colour	Grey
Weight	32.82 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Pressure	30 bars

Drawings

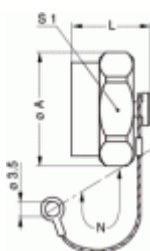

Dimensions

	A	L	N	S1
mm.	27.8	14.7	120	26
in.	1.09	0.58	4.72	1.02

https://www.lemo.com/int_en/bre-3v-200-sav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.