



Image for illustrative purpose only

## Summary

<a href="#">Request a quote</a>	
<a href="#">Catalog</a>	
Size	4K
Series	K - Outdoor keyed

# Technical details


## Form & Material

Shell style / Model id	BRE - Cap for receptacle
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Keying	No keying
Colour	Grey
Weight	62.01 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Temperature range	-50°C / +135°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]

# Drawings

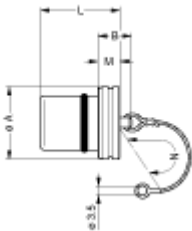

No keying

## Dimensions

	A	B	L	M	N
mm.	30	20	30.5	10	120
in.	1.18	0.79	1.2	0.39	4.72

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/bre-4k-200-sas.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/bre-4k-200-sas.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.