



## Summary

[Request a quote](#)

[Catalog](#)

Locking system Threaded

Size 4V

## Technical details

### Form & Material

Shell style / Model id BRE - Cap for receptacle

Housing material Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces

Locking system Threaded

Keying Circular, female

Weight 47.94 g

### Environment

Environmental protection (IP rating) No IP rating

Minimal temperature -20°C / +135°C

Climatical Category 20/200/21

Shielding (min) 95 dB (10 MHz)

Shielding (min) 80 dB (1 GHz)


Pressure 30 bars

Salt Spray Corrosion >144 hr

[https://www.lemo.com/int\\_en/bre-4v-200-nav.html](https://www.lemo.com/int_en/bre-4v-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

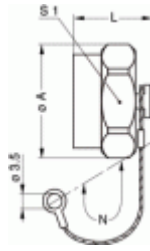

## Dimensions

	<b>A</b>	<b>L</b>	<b>N</b>	<b>S1</b>
mm.	34.3	14.7	120	32
in.	1.35	0.58	4.72	1.26

[https://www.lemo.com/int\\_en/bre-4v-200-nav.html](https://www.lemo.com/int_en/bre-4v-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.