



Summary

[Request a quote](#)

[Catalog](#)

Size	0K
Series	K - Outdoor keyed

Technical details

Form & Material

Shell style / Model id	BRF - Cap for free receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Keying	No keying
Weight	10.43 g


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental protection (IP rating)	No IP rating
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/brf-0k-200-nps.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Drawings

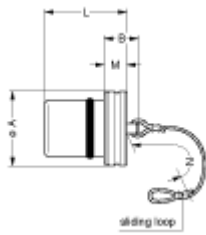

No keying

Dimensions

	A	B	L	M	N
mm.	15	10	15	4	85
in.	0.59	0.39	0.59	0.16	3.35

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/brf-0k-200-nps.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.