



Image for illustrative purpose only

## Summary

<a href="#">Request a quote</a>	
<a href="#">Catalog</a>	
Locking system	Threaded
Size	0V

# Technical details


## Form & Material

Shell style / Model id	BRF - Cap for receptacle
Housing material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Locking system	Threaded
Keying	Circular, female
Colour	Grey
Weight	12.84 g

## Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Pressure	30 bars
Salt Spray Corrosion	>144 hr

## Drawings

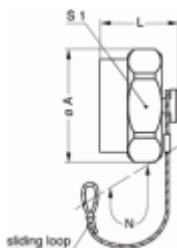

## Dimensions

	A	L	N	S1
mm.	17.2	13.7	85	16
in.	0.68	0.54	3.35	0.63

[https://www.lemo.com/int\\_en/brf-0v-200-nav.html](https://www.lemo.com/int_en/brf-0v-200-nav.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.