



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Locking system	Threaded
Size	1V

https://www.lemo.com/int_en/brf-1v-200-sav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BRF - Cap for receptacle
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	Circular, female
Colour	Grey
Weight	15.69 g

Environment

Environmental sealing (IP rating)	IP68
Temperature range	-20°C / +135°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars

Drawings

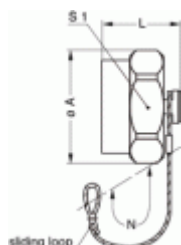

Dimensions

	A	L	N	S1
mm.	19.3	13.7	85	18
in.	0.76	0.54	3.35	0.71

https://www.lemo.com/int_en/brf-1v-200-sav.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.