



## Summary

[Request a quote](#)

---

[Catalog](#)

---

Size	0S
------	----

---

Series	S - Indoor Stepped Insert
--------	---------------------------

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/brr-0s-200-pzvn.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-0s-200-pzvn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details


## Form & Material

Shell style / Model id	BRR - Cap spring loaded dust cap for ERA,ERN and EG receptacle or PSA and PK fixed receptacle
Housing material	PSU(Polysulfone) shell without treatment, FKM (VITON®)
Keying	Circular, female
Colour	Black
Variant	Black
Weight	0.5 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Temperature range	-50°C / +150°C
Axes material	Nickel-plated brass
Maximum operating temperature	100°C
Watertightness	IP61 according to IEC 60529

## Drawings

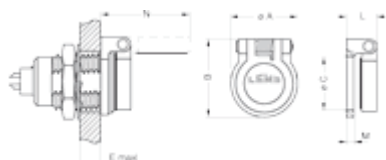

## Dimensions

	<b>A</b>	<b>B</b>	<b>C</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>N</b>
mm.	11	13.3	9	5.8	5	1.2	15.3
in.	0.43	0.52	0.35	0.23	0.2	0.05	0.6

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/brr-0s-200-pzvn.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-0s-200-pzvn.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.