



Image for illustrative purpose only

## Summary

<a href="#">Request a quote</a>	
<a href="#">Catalog</a>	
Size	2S
Series	S - Indoor Stepped Insert

# Technical details


## Form & Material

Shell style / Model id	BRR - Cap spring loaded dust cap for ERA,ERN and EG receptacle or PSA and PK fixed receptacle
Housing material	PSU(Polysulfone) shell without treatment, FKM (VITON®)
Keying	Circular, female
Colour	Grey
Weight	1.9 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +150°C
Axes material	Nickel-plated brass
Maximum operating temperature	100°C
Watertightness	IP61 according to IEC 60529

## Drawings

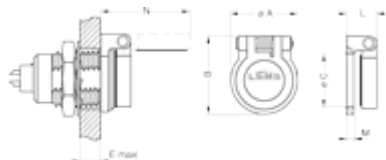

## Dimensions

	A	B	C	E	L	M	N
mm.	18.6	22.4	15.2	6.5	8.2	2	26.2
in.	0.73	0.88	0.6	0.26	0.32	0.08	1.03

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/brr-2s-200-pzvg.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-2s-200-pzvg.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.