



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Size	3S
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details


Form & Material

Shell style / Model id	BRR - Cap spring loaded dust cap for ERA,ERN and EG receptacle or PSA and PK fixed receptacle
Housing material	PSU(Polysulfone) shell without treatment, FKM (VITON®)
Keying	Circular, female
Colour	Black
Variant	Black
Weight	3.1 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP61
Temperature range	-50°C / +150°C
Axes material	Nickel-plated brass
Maximum operating temperature	100°C
Watertightness	IP61 according to IEC 60529

Drawings

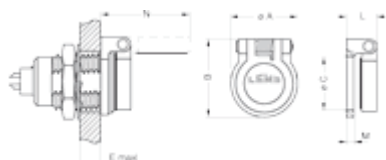

Dimensions

	A	B	C	E	L	M	N
mm.	22.5	26.5	18.2	9	8.8	2.5	30.8
in.	0.89	1.04	0.72	0.35	0.35	0.1	1.21

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/brr-3s-200-pzvn.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.