



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Plug	Plug - Bridge
Locking system	Snap-on
Size	0A

[https://www.lemo.com/int\\_en/cff-0a-275-ptchv.html](https://www.lemo.com/int_en/cff-0a-275-ptchv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Coax	1
Insert configuration value	0A.275 - 1 Coax (75 Ohm)
Rated current	2 A
OHM	75


## Form & Material

Shell style / Model id	CFF - Bridge plug with two non-latching plugs
Plug	Bridge
Housing material	PA.6 (Polyamide 6) shell, other pieces nickel plated [SAE AMS QQ N 290] brass
Locking system	Snap-on
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	10.94 g

## Environment

Environmental sealing (IP rating)	IP50
Endurance	1000 mating cycles
R leak (He) (max)	0.0000001 mbar*l/s (if vacuum-tested)

## Drawings

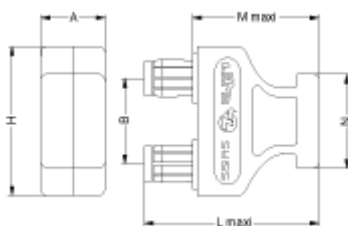

## Dimensions

	<b>B</b>	<b>L</b>	<b>M</b>	<b>N</b>	<b>H</b>	<b>A</b>
mm.	14	37.2	27.2	22.5	27.5	13.5
in.	0.55	1.46	1.07	0.89	1.08	0.53

[https://www.lemo.com/int\\_en/cff-0a-275-ptchv.html](https://www.lemo.com/int_en/cff-0a-275-ptchv.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.