



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	2
Number of contacts Low Voltage	3
Gender	Standard
Plug	Plug - Bridge
Locking system	Snap-on
Size	0B
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Thermocouple	2
Insert configuration value	0B.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	8 A
Contact Dia.	0.9 mm (0.04in)
Number of contacts Low Voltage	3
Gender	Standard

## Form & Material

Shell style / Model id	CRF - Bridge plug with two non-latching plugs with monitoring output
Plug	Bridge
Housing material	PA.6 (Polyamide 6) shell without treatment, other pieces nickel plated [SAE AMS QQ N 290] brass
Locking system	Snap-on
Keying	B: 2 keys (alpha=60, plug: male contacts, receptacle: female contacts)
Colour	Orange
Variant	Orange



## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-20°C / +90°C
Climatical Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>144 hr

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

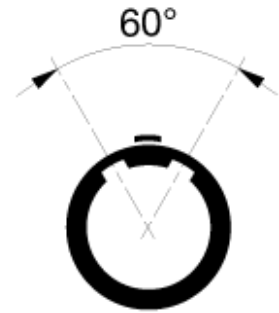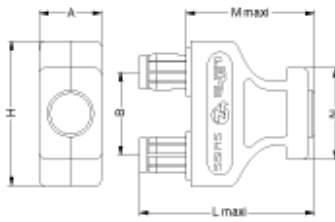

## Dimensions

	<b>B</b>	<b>L</b>	<b>M</b>	<b>N</b>	<b>H</b>	<b>A</b>
mm.	14	37.2	27.2	22.5	27.5	13.5
in.	0.55	1.46	1.07	0.89	1.08	0.53

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/crb-0b-303-ples.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.