



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Plug	Plug - Bridge
Locking system	Snap-on
Size	0A

https://www.lemo.com/int_en/crf-0a-275-pten.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Nb of contacts Coax	1
Insert configuration value	0A.275 - 1 Coax (75 Ohm)
Rated current	2 A
OHM	75


Form & Material

Shell style / Model id	CRF - Bridge plug with two non-latching plugs with monitoring output
Plug	Bridge
Housing material	PA.6 (Polyamide 6) shell, other pieces nickel plated [SAE AMS QQ N 290] brass
Locking system	Snap-on
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Black
Variant	Black
Weight	14.96 g

Environment

Environmental sealing (IP rating)	IP50
Endurance	1000 mating cycles

Drawings

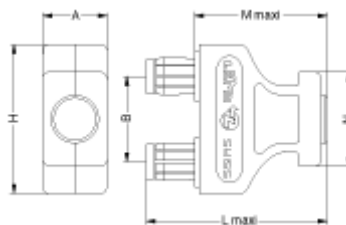

Dimensions

	B	L	M	N	H	A
mm.	14	37.7	27.2	22.5	27.5	13.5
in.	0.55	1.48	1.07	0.89	1.08	0.53

https://www.lemo.com/int_en/crf-0a-275-pten.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.