



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	5
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Size	1S
Matching parts	<a href="#">FFP.1S.305.CLAC37</a>
Series	S - Indoor Stepped Insert

## Technical details

### Electrical Configuration

Contact Termination Low voltage	PCB - Straight
Insert configuration value	1S.305 - 2 (0.9 mm) + 3 (0.7 mm) Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	2x0.9 contacts : 10 Amps and 3x0,7 contacts : 7 Amps
Vtest	1500 V (AC), 2100 V (DC)
Contact Type	Print (straight)
Number of contacts Low Voltage	5

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Form & Material

Shell style / Model id	ECP - Fixed receptacle with two nuts, long threaded shell, with straight contact for printed circuit (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Weight	10.45 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Drawings

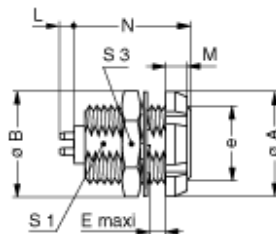

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>S3</b>	<b>S1</b>	<b>N</b>	<b>M</b>	<b>E</b>	<b>e</b>	<b>B</b>	<b>A</b>
mm.	14	10.5	17.5	3.5	10	M12x1.0	16	16
in.	0.55	0.41	0.69	0.14	0.39		0.63	0.63

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ecp-1s-305-cln.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.