



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Size	3N
Suggested matching part	FZG.3N.304.TYCY12
Series	N - Nuclear Stainless Steel

Technical details

Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Crimp
Insert configuration value	3N.304 - 4 Low Voltage
Insulator	Y: PEEK
Rated current	19 A


Form & Material

Shell style / Model id	EDG - Fixed receptacle with square flange, 4 screw fixing, with long pre-positioning sleeve
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Stainless steel shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Push-Pull latch for manipulator. Female contacts
Colour	Grey
Weight	188.99 g

Environment

Technical domain	Energy and Industrial, Specialties and Other
Environmental sealing (IP rating)	IP66

Drawings

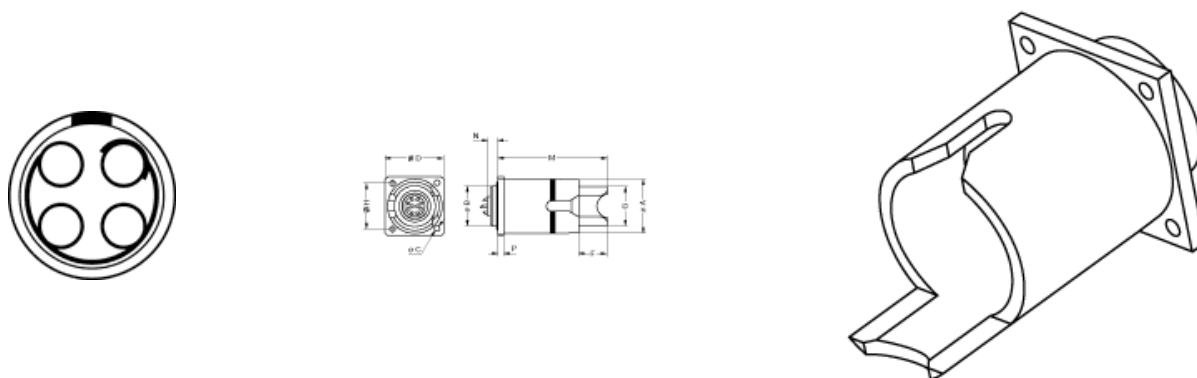

https://www.lemo.com/int_en/solutions/supreme/n-nuclear-stainless-steel/edg-3n-304-tym.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	C	D	F	G	H	M	N	P
mm.	32	24	3.2	34	18.5	19	27	68.5	8.7	3
in.	1.26	0.94	0.13	1.34	0.73	0.75	1.06	2.7	0.34	0.12

Recommended By Lemo

Accessories

Replacement contact	EGG.3B.675.ZZM
---------------------	--------------------------------

Tools

Positionner	DCE.91.203.BVCM
Extraction tool	DCC.20.25B.LAG