



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	8
Wire Size/AWG	26 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.80 - 10.70 mm
Size	1F
Matching parts	<a href="#">FGN.1F.308.CLC</a>
Series	F - Rugged Push-Pull

## Technical details

[https://www.lemo.com/int\\_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html](https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	1F.308 - 8 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5 Amps
Vtest (contact-contact)	1300 V (AC), 1840 V (DC)
Vtest (contact-shell)	1300 V (AC), 1840 V (DC)
Contact retention	22 N
Contact Type	Crimp
Max. Conductor	0.34 mm <sup>2</sup> (AWG 22)
Min. Conductor	0.14 mm <sup>2</sup> (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Number of contacts Low Voltage	8
Wire Size/AWG	26 - 22
Gender	Standard

## Form & Material

Shell style / Model id	EE - Fixed receptacle, nut fixing (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and nut, other pieces brass
Locking system	Push-pull
Keying	3 keys (beta=165, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	11.88 g

[https://www.lemo.com/int\\_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html](https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Motorsport, Security and Defence
Environmental protection (IP rating)	IP50
Minimal temperature	-55°C / +200°C
Climatical Category	50/175/21 (Aluminium shell)
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Jacket cable outside diameter [mm]	3.80 - 10.70 mm
------------------------------------	-----------------

## Drawings

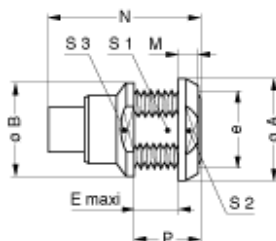

## Dimensions

	B	e	E	S3	S2	A	S1	P	N	M
mm.	15	M13x0.75	6.2	14	14	17	11.5	9.4	19	3.2
in.	0.59		0.24	0.55	0.55	0.67	0.45	0.37	0.75	0.13

## Recommended By Lemo

### Accessories

Replacement contact	<a href="#">EGG.0B.655.ZZM</a>
---------------------	--------------------------------






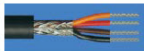







### Tools

Positionner	<a href="#">DCE.91.070.BVM</a>
Extraction tool	<a href="#">DCF.93.070.4LT</a>
Crimp tool	<a href="#">DPC.91.701.V</a>

[https://www.lemo.com/int\\_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html](https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Cables

Cable PartNumber	Material	Colour	Cable image
CMN.08.T22.059QGC	TPR	Grey	
CMN.08.T22.059QGZE	TPR (medical)	Grey	
CMN.08.T26.042QGZE	TPR (medical)	Grey	
108220	PVC	Black	
108240	PTFE	White	
108260	PTFE	White	
16080	PVC	Grey	
180240	PVC	Black	
180260	PVC	Black	
280250	PVC	Grey	
335990	PVC	Black	
335991	PVC	Black	
42265	PVC	Yellow	
80140	PVC	Grey	
8050	PVC	Black	
8280	PVC	Black	

[https://www.lemo.com/int\\_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html](https://www.lemo.com/int_en/solutions/optima/f-rugged-push-pull/een-1f-308-clm.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.