



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Fluidic	1
Jacket cable outside diameter [mm]	1.60 - 6.20 mm
Size	0R
Suggested matching part	<a href="#">FGG.0R.010.AZA05</a>

[https://www.lemo.com/int\\_en/egg-0r-010-azl05.html](https://www.lemo.com/int_en/egg-0r-010-azl05.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Fluidic	1
Contact Termination Fluidic	Solder
Contact Type	Solder

## Form & Material

Shell style / Model id	EGG - Female fluidic / pneumatic contact
Housing material	Stainless steel
Keying	No keying
Weight	0.61 g


## Environment

Environmental sealing (IP rating)	No IP rating
-----------------------------------	--------------

## Cable fixation

Jacket cable outside diameter [mm]	1.60 - 6.20 mm
------------------------------------	----------------

# Drawings

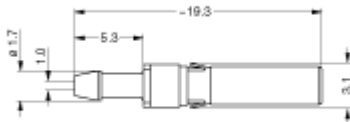

**No keying**

[https://www.lemo.com/int\\_en/egg-0r-010-azl05.html](https://www.lemo.com/int_en/egg-0r-010-azl05.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.