



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	6
Wire Size/AWG	28 - 20
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Size	2B
Suggested matching part	<a href="#">FGG.2B.903.CLEF82</a>
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/egg-2b-903-cle.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-2b-903-cle.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Thermocouple	6
Contact Termination Thermocouple	Solder
Insert configuration value	2B.903/ThC - 3 Thermocouple Pairs
Insulator	L: PEEK (UL 94 / V-0/1.5)
ThC. Materials (P+/N-)	Chromel / Constantan
Contact Dia.	1.3
Wire Size/AWG	28 - 20
Gender	Standard

## Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	15.61 g

 


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-40°C / +80°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/egg-2b-903-cle.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-2b-903-cle.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Drawings

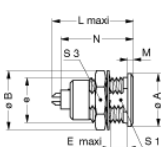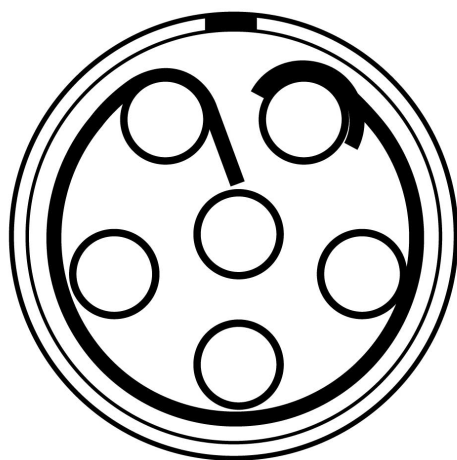

Contact 1, 3, 5: Chromel (+)  
Contact 2, 4, 6: Konstantan (-)

## Dimensions

	A	B	e	E	L	M	N	S3	S1
mm.	18	19.5	M15x1.0	8.5	26.7	1.8	24.6	17	13.5
in.	0.71	0.77		0.33	1.05	0.07	0.97	0.67	0.53

# Recommended By Lemo

## Accessories

Compatible cap	<a href="#">BRE.2S.200.NAS</a>
----------------	--------------------------------

## Tools

Spanner	<a href="#">DCA.91.231.7TN</a>
---------	--------------------------------