



Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Number of contacts Low Voltage | 10 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 2.00 - 16.60 mm |
| Size | 3B |
| Matching parts | FGG.3B.310.CLAD12 |
| Series | B - Indoor keyed |

Technical details

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-310-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

| | |
|---------------------------------|------------------------------|
| Contact Termination Low voltage | Solder |
| R (max) | 3.6 mOhm |
| Insert configuration value | 3B.310 - 10 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 12 Amps |
| Vtest (contact-contact) | 1250 V (AC), 1770 V (DC) |
| Vtest (contact-shell) | 900 V (AC), 1270 V (DC) |
| Contact Type | Solder |
| Max. Solid Conductor | 0.5 mm ² (AWG 20) |
| Max. Stranded Conductor | 0.5 mm ² (AWG 20) |
| Bucket Dia. | 1 mm (0.039in) |
| Contact Dia. | 1.3 mm (0.051in) |
| Number of contacts Low Voltage | 10 |
| Wire Size/AWG | 28 - 20 |
| Gender | Standard |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | EG - Fixed receptacle, nut fixing |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | 1 key (alpha=0, plug: male contacts, receptacle: female contacts) |
| Weight | 27.47 g |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-310-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

| | |
|--------------------------------------|--|
| Technical domain | Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV |
| Environmental protection (IP rating) | IP50 |
| Minimal temperature | -55°C / +250°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 75 dB (10 MHz) |
| Shielding (min) | 40 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------------|-----------------|
| Jacket cable outside diameter [mm] | 2.00 - 16.60 mm |
|------------------------------------|-----------------|

Recommended By Lemo

Accessories




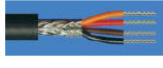
Tools

| | |
|---------|--------------------------------|
| Spanner | DCA.91.282.2TN |
|---------|--------------------------------|

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-310-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|---------------|--------|---|
| CMN.10.T20.080PGZE | | grey |  |
| CMN.10.T20.080PNZE | | |  |
| CMN.10.T20.080QGC | TPR | Grey | |
| CMN.10.T22.068QGZE | TPR (medical) | Grey |  |
| CMN.10.T28.052PGZE | | grey |  |
| CMN.10.T28.052PNZE | | |  |
| CMN.10.T28.053QGZE | TPR (medical) | Grey |  |
| 110220 | PVC | Black |  |
| 110240 | PTFE | White |  |
| 110260 | PTFE | White |  |
| 110280 | PVC | Black |  |
| 210140 | PVC | Grey |  |
| 210240 | PVC | Black |  |
| 210250 | PVC | Grey |  |
| 210260 | PVC | Black |  |

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/egg-3b-310-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.