



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 22.60 mm
Size	3K
Suggested matching part	FGG.3K.8H2.CJCC101
Series	K - Outdoor keyed

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-8h2-cjm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

R (max)	5.8 mOhm
Insulator	J: PEEK/PEEK
Rated current	2 A
Max. Conductor	0.34 mm ² (AWG 22)
Min. Conductor	0.34 mm ² (AWG 22)
Contact Dia.	0.7 mm (0.03in)
Gender	Standard

Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	69.8 g

Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-8h2-cjm1.html



LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Jacket cable outside diameter [mm]

2.00 - 22.60 mm

Drawings

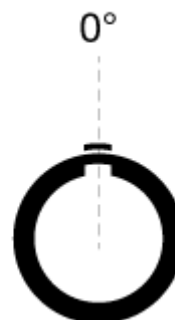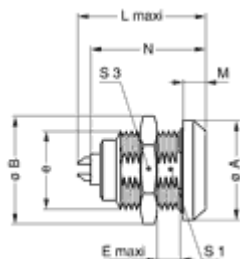

Dimensions

	e	E	L	M	N	S1	S3	A	B
mm.	M24x1.0	11	36.2	6	33.6	22.5	30	31	34.5
in.		0.43	1.43	0.24	1.32	0.89	1.18	1.22	1.36

Recommended By Lemo

Accessories

Replacement contact [EGG.3B.660.ZZM](#)

Compatible cap [BRE.3K.200.NAS](#)

Tools

Die Tool [DPE.99.103.8K](#)

Positionner [DCE.91.093.BVM](#)

Extraction tool [DCC.09.05B.LAG](#)

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egg-3k-8h2-cjm1.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.