



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	30
Wire Size/AWG	26 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.00 - 16.60 mm
Size	3T
Suggested matching part	<a href="#">FGG.3T.330.CYCK14</a>
Series	T - Small Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	30
Contact Termination Low voltage	Crimp
R (max)	6.1 mOhm
Insert configuration value	T.330 - 30 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	3.5 A
Vtest (contact-contact)	2 kV (DC)
Vtest (contact-shell)	1.7 kV (DC)
Contact retention	22 N
Max. Conductor	0.34 mm <sup>2</sup> (AWG 22)
Min. Conductor	0.14 mm <sup>2</sup> (AWG 26)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	26 - 22
Gender	Standard

## Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	18.68 g

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

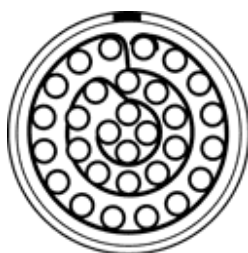
## Environment

Environmental sealing (IP rating)	IP68
Endurance	>3000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Resistance to vibration	15 g [10 Hz - 2000 Hz]
Shock Resistance	100 g [ 6 ms]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Jacket cable outside diameter [mm]	2.00 - 16.60 mm
------------------------------------	-----------------

## Drawings



## Dimensions

	A	B	e	E	L	M	N	S1	S2
mm.	23.5	25.1	M18x1.0	9.6	30.1	2.5	25	16.5	22
in.	0.93	0.99		0.38	1.19	0.1	0.98	0.65	0.87

## Recommended By Lemo

### Accessories

Replacement contact	<a href="#">EGG.3B.655.ZZM</a>
Compatible cap	<a href="#">BRE.3T.200.CAZ</a>





 

 
[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Tools

Spanner	<a href="#">DCA.91.282.2TN</a>
Positionner	<a href="#">DCE.91.073.BVM</a>
Extraction tool	<a href="#">DCC.07.04B.LAG</a>
Crimp tool	<a href="#">DPC.91.701.V</a>

## Cables

Cable PartNumber	Material	Colour	Cable image
CMN.30.T22.087PGCE	PVC	GREY	
CMN.30.T22.087PGZE		grey	
CMN.30.T22.087PNCE	PVC	Black	
CMN.30.T22.087PNZE			
330240	PVC	Black	
330260	PVC	Black	
430250	PVC	Grey	

[https://www.lemo.com/int\\_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html](https://www.lemo.com/int_en/solutions/originals/t-outdoor-keyed/egg-3t-330-cym.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.