



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	30
Wire Size/AWG	30 - 22
Gender	Reverse Gender
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.00 - 28.60 mm
Size	4K
Suggested matching part	<a href="#">FGL.4K.330.CLLC95</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	4.8 mOhm
Insert configuration value	4K.330 - 30 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	5 A
Vtest (contact-contact)	950 V (AC), 1340 V (DC)
Vtest (contact-shell)	850 V (AC), 1200 V (DC)
Contact Type	Solder
Max. Solid Conductor	0.34 mm <sup>2</sup> (AWG 22)
Max. Stranded Conductor	0.34 mm <sup>2</sup> (AWG 22)
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.9 mm (0.035in)
Number of contacts Low Voltage	30
Wire Size/AWG	30 - 22
Gender	Reverse Gender

## Form & Material

Shell style / Model id	EG - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=75, plug: female contacts, receptacle: male contacts)
Weight	106.97 g

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

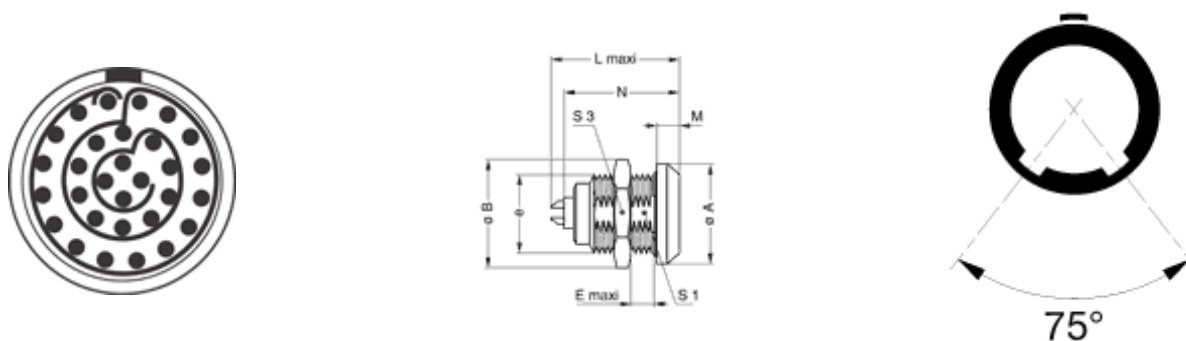
## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Jacket cable outside diameter [mm]	4.00 - 28.60 mm
------------------------------------	-----------------

## Drawings



## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>N</b>	<b>S3</b>	<b>S1</b>
mm.	37	41.5	M30x1.0	9	40.2	6.5	38.6	36	28.5
in.	1.46	1.63		0.35	1.58	0.26	1.52	1.42	1.12

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo





 
 

Accessories

---

Tools

---

## Cables

Cable PartNumber	Material	Colour	Cable image
CMN.30.T22.087PGCE	PVC	GREY	
CMN.30.T22.087PGZE		grey	
CMN.30.T22.087PNCE	PVC	Black	
CMN.30.T22.087PNZE			
330240	PVC	Black	
330260	PVC	Black	
430250	PVC	Grey	

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/egl-4k-330-cla.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.