



Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Number of contacts Low Voltage	10
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	9.60 - 42.60 mm
Size	5E
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Nb of contacts Coax	1
Contact Termination Coax	Solder
Insert configuration value	5E.810 - 1 Coax (50 Ohm), 10 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Number of contacts Low Voltage	10

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-5e-810-cll3.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	ERA - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Weight	261.05 g


Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Jacket cable outside diameter [mm]	9.60 - 42.60 mm
------------------------------------	-----------------

Drawings

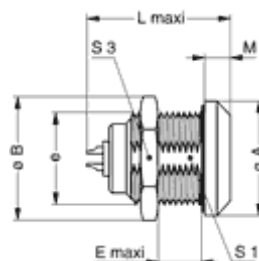

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-5e-810-cll3.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Dimensions

	A	B	e	E	L	M	S1
mm.	55	54	M45x1.5	10	44.5	9	42.5
in.	2.17	2.13		0.39	1.75	0.35	1.67

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/era-5e-810-cll3.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.