



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	18
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	5.00 - 33.60 mm
Size	5S
Series	S - Indoor Stepped Insert

## Technical details

### Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	5S.318 - 2 (3 mm) + 16 (1.6 mm) Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	2x3.0 contacts: 18 Amps and 16x1.6 contacts: 11 Amps
Vtest	1800 V (AC), 2400 V (DC)
Contact Type	Solder
Number of contacts Low Voltage	18

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	ERA - Fixed receptacle, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Weight	133.51 g



## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Jacket cable outside diameter [mm]	5.00 - 33.60 mm
------------------------------------	-----------------

## Drawings

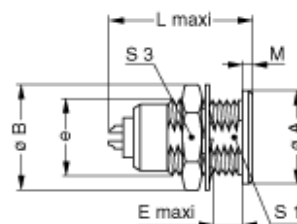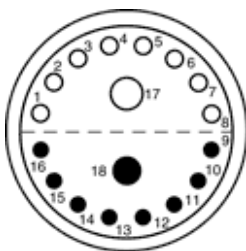

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>A</b>	<b>B</b>	<b>e</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>S1</b>
mm.	40	40	M35x1.0	15.5	45	3	33.5
in.	1.57	1.57		0.61	1.77	0.12	1.32

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/era-5s-318-cll.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.