



Summary

[Request a quote](#)

[Catalog](#)

| | |
|------------------------------------|---|
| Number of contacts Low Voltage | 2 |
| Wire Size/AWG | 28 - 20 |
| Socket / Receptacle | Socket / Receptacle - Fixed Panel Front Mounted |
| Locking system | Push-pull |
| Jacket cable outside diameter [mm] | 1.00 - 10.60 mm |
| Size | 1S |
| Matching parts | FFA.1S.302.CLAC32 |
| Series | S - Indoor Stepped Insert |

Technical details

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/erc-1s-302-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Electrical Configuration

| | |
|---------------------------------|------------------------------|
| Contact Termination Low voltage | Solder |
| R (max) | 3.6 mOhm |
| Insert configuration value | 1S.302 - 2 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated current | 15 Amps |
| Vtest | 1200 V (AC), 1800 V (DC) |
| Contact Type | Solder |
| Max. Solid Conductor | 0.5 mm ² (AWG 20) |
| Max. Stranded Conductor | 0.5 mm ² (AWG 20) |
| Bucket Dia. | 1 mm (0.039in) |
| Contact Dia. | 1.3 mm (0.051in) |
| Number of contacts Low Voltage | 2 |
| Wire Size/AWG | 28 - 20 |

Form & Material

| | |
|------------------------|---|
| Shell style / Model id | ERC - Fixed receptacle, nut fixing with slot in the flange |
| Socket / Receptacle | Fixed Panel Front Mounted |
| Housing material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system | Push-pull |
| Keying | Hermaphroditic keying (half moon insert) with female pin 1 |
| Weight | 8.52 g |

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/erc-1s-302-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

| | |
|-----------------------------------|---|
| Technical domain | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental sealing (IP rating) | IP50 |
| Endurance | 5000 mating cycles |
| Temperature range | -55°C / +250°C |
| Climatical Category | 50/175/21 |
| Humidity (max) | <=95% [at 60 deg C /140 F] |
| Shielding (min) | 75 dB (10 MHz) |
| Shielding (min) | 40 dB (1 GHz) |
| Shock Resistance | 100 g [6 ms] |
| Vibration | 15 g [10 Hz - 2000 Hz] |
| Salt Spray Corrosion | >1000 hr |

Cable fixation

| | |
|------------------------------------|-----------------|
| Jacket cable outside diameter [mm] | 1.00 - 10.60 mm |
|------------------------------------|-----------------|

Drawings

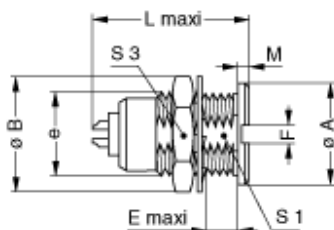

Dimensions

| | A | B | e | E | F | L | M | S1 | S3 |
|-----|----------|----------|----------|----------|----------|----------|----------|-----------|-----------|
| mm. | 14 | 16 | M12x1.0 | 7.5 | 2.5 | 20.2 | 1.5 | 10.5 | 14 |
| in. | 0.55 | 0.63 | | 0.3 | 0.1 | 0.8 | 0.06 | 0.41 | 0.55 |

Recommended By Lemo

Accessories

Tools




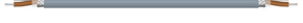















Spanner wrench

[Socket for torque wrench DCM.1S.M12.4](#)

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/erc-1s-302-cll.html














LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cables

| Cable PartNumber | Material | Colour | Cable image |
|--------------------|---------------|--------|---|
| CMN.02.T20.047PGZE | | grey |  |
| CMN.02.T20.047PNZE | | |  |
| CMN.02.T20.048QGZE | TPR (medical) | Grey |  |
| CMN.02.T28.030PGCE | PVC | GREY |  |
| CMN.02.T28.030PGZE | | grey |  |
| CMN.02.T28.030PNCE | PVC | Black |  |
| CMN.02.T28.030PNZE | | |  |
| 102080 | PVC | Grey | |
| 120184 | PVC | Black |  |
| 120240 | PVC | Black |  |
| 120250 | PVC | Grey |  |
| 120500 | PVC | Grey |  |
| 120501 | PVC | Grey |  |
| 120751 | PVC | Grey |  |
| 20140 | PVC | Grey |  |
| 20140 | PVC | Grey |  |
| 20141 | PVC | Grey |  |
| 20142 | PVC | Red |  |
| 20143 | PVC | Green |  |
| 20144 | PVC | Black |  |

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/erc-1s-302-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

| Cable PartNumber | Material | Colour | Cable image |
|------------------|----------|--------|---|
| 20145 | PVC | Yellow |  |
| 20146 | PVC | Black |  |
| 20240 | PTFE | White |  |
| 20260 | PVC | Black |  |
| 20264 | PVC | Black |  |
| 20266 | PVC | Violet |  |
| 2050 | PVC | Black |  |
| 20550 | PUR | Black |  |
| 20560 | PUR | White |  |
| 2080 | PVC | Grey | |
| 220750 | PVC | Grey |  |
| 2221 | PVC | Black |  |
| 2260 | PTFE | White |  |
| 2280 | PVC | Black |  |
| 4082 | PVC | Grey | |
| CMB.02.210.635 | PUR | Black | |

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/erc-1s-302-cll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.