

Summary

[Request a quote](#)

[Catalog](#)

Triax	1
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Threaded
Size	2V
Matching parts	FVN.2V.650.TLAC75

Technical details

Electrical Configuration

Triax	1
Contact Termination Triax	Solder
Insert configuration value	2V.650 - 1 Triax (50 Ohm)
Contact Type	Solder

Form & Material

Shell style / Model id	EVP - Fixed socket, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Locking system	Threaded
Keying	Circular, female
Weight	44.05 g


https://www.lemo.com/int_en/evp-2v-650-tll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Environmental protection (IP rating)	IP68
Minimal temperature	-20°C / +200°C
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars

Drawings

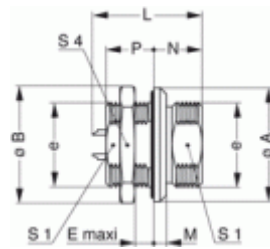

Dimensions

	A	B	e	E	L	M	N	P	S1	S4
mm.	26	27	M20x1.0	11	29	2.5	9	15	18.5	24
in.	1.02	1.06		0.43	1.14	0.1	0.35	0.59	0.73	0.94

https://www.lemo.com/int_en/evp-2v-650-tll.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.