

Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Socket / Receptacle	Socket / Receptacle - Fixed Panel Front Mounted
Locking system	Threaded
Size	3V
Suggested matching part	FVN.3V.405.STAK13

Technical details

Electrical Configuration

Insert configuration value	3V.405 - 1 High Voltage
----------------------------	-------------------------


Form & Material

Shell style / Model id	EVP - Fixed socket, nut fixing
Socket / Receptacle	Fixed Panel Front Mounted
Housing material	Stainless steel shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Threaded
Keying	Circular, female
Colour	Grey

Environment

Environmental sealing (IP rating)	IP68
Endurance	1000 mating cycles
Temperature range	-20°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	20/200/21
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Pressure	30 bars

Drawings

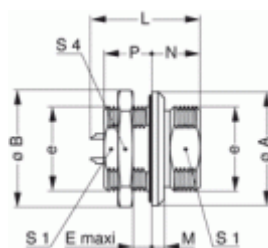

Dimensions

	A	B	e	E	L	M	N	P	S1	S4
mm.	31	34	M24x1.0	15	34.5	3	9.5	20	22.5	30
in.	1.22	1.34		0.59	1.36	0.12	0.37	0.79	0.89	1.18

https://www.lemo.com/int_en/evp-3v-405-stl.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories

Compatible cap	BRE.3V.200.SAV
----------------	--------------------------------