



Image for illustrative purpose only

## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	4
Nb of contacts Coax	1
Wire Size/AWG	30 - 22
Gender	Standard
Plug	Plug - Fixed
Locking system	Snap-on
Size	2K
Suggested matching part	<a href="#">PHG.2K.804.CLLC01Z</a>
Series	K - Outdoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts Low Voltage	4
Contact Termination Low voltage	Solder
Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Contact Termination Coax - Screen fixing	Collet
R (max)	3.8 mOhm
Insert configuration value	2K.804 - 1 Coax (50 Ohm), 4 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 A
OHM	50
Test voltage (kV DC)	1.05
Max. Solid Conductor	0.5 mm <sup>2</sup> (AWG 20)
Max. Stranded Conductor	0.14 mm <sup>2</sup> (AWG 26)
Cable type	RG 178 B/U, RG 196 A/U
Contact Dia.	0.7 mm (0.028in)
Wire Size/AWG	30 - 22
Gender	Standard

## Form & Material

Shell style / Model id	FA - Fixed plug, non-latching, nut fixing
Plug	Fixed
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Snap-on
Keying	G: 1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Weight	42.82 g

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

## Drawings

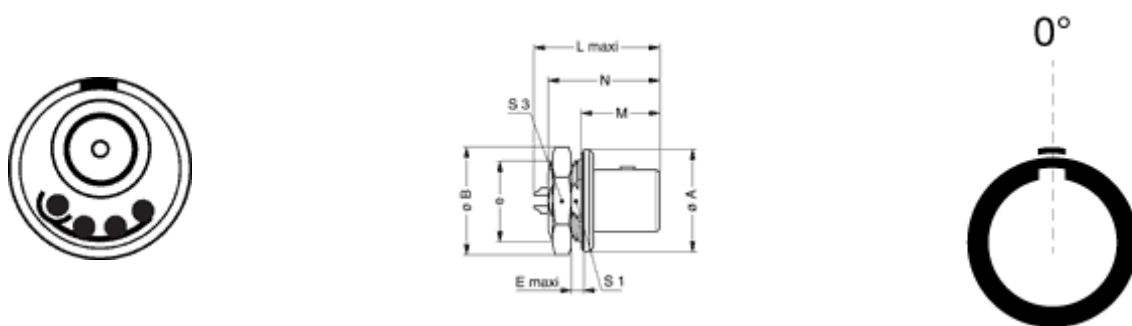

## Dimensions

	<b>e</b>	<b>A</b>	<b>B</b>	<b>E</b>	<b>S3</b>	<b>S1</b>	<b>L</b>	<b>M</b>	<b>N</b>
mm.	M20x1.0	25	27.5	4.5	24	18.5	33.6	18	28.3
in.		0.98	1.08	0.18	0.94	0.73	1.32	0.71	1.11

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Tools

---

Die Tool

[DCP.99.050.TC](#)

[https://www.lemo.com/int\\_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html](https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fag-2k-804-cla2.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.