



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

Number of contacts High Voltage	21
Wire Size/AWG	30 - 22
Gender	Reverse Gender
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	18.00 - 22.00 mm
Size	5B
Suggested matching part	<a href="#">EGJ.5B.481.CLA</a>
Series	B - Indoor keyed

[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fcj-5b-481-clly22.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fcj-5b-481-clly22.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Number of contacts High Voltage	21
Contact Termination High voltage	Solder
Insert configuration value	5B.481 - 21 High Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	4 A
Vtest	12700 V (AC), 18000 V (DC)
Wire Size/AWG	30 - 22
Gender	Reverse Gender

## Form & Material

Shell style / Model id	FC - Straight plug, cable clamp and safety locking ring
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (alpha=37.5, plug: female contacts, receptacle: male contacts)
Colour	Grey
Weight	303.28 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


[https://www.lemo.com/int\\_en/solutions/originals/b-indoor-keyed/fcj-5b-481-clly22.html](https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fcj-5b-481-clly22.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	18.00 - 22.00 mm

Drawings

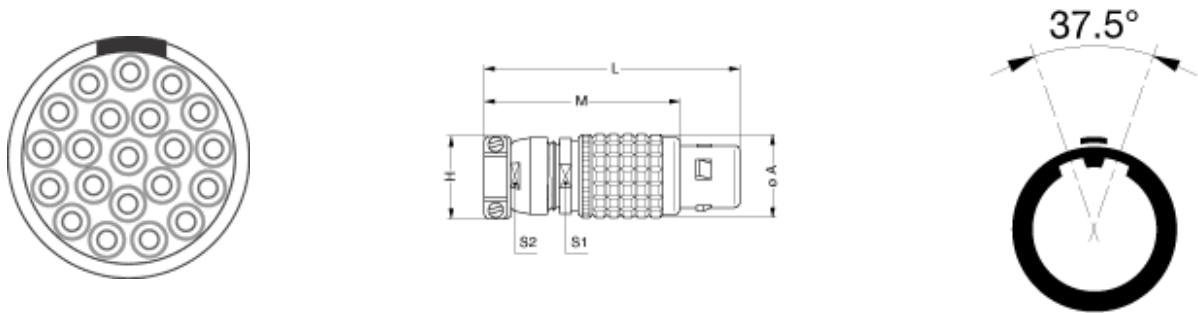

Dimensions

	A	L	M	S1	S2	H
mm.	35	107	82	31	30	34
in.	1.38	4.21	3.23	1.22	1.18	1.34