



## Summary

[Request a quote](#)

[Catalog](#)

Triax	1
Plug	Plug - Fixed
Locking system	Push-pull
Size	T7

## Technical details

### Electrical Configuration

Triax	1
Contact Termination Triax	Solder
Contact Type	Solder

### Form & Material

Shell style / Model id	FEZ - Fixed plug, crimp, nut fixing
Plug	Fixed
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male

[https://www.lemo.com/int\\_en/fez-t7-675-cta01s.html](https://www.lemo.com/int_en/fez-t7-675-cta01s.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

Environmental protection (IP rating)	IP68
Minimal temperature	-55°C / +250°C
Humidity (max)	<=95% [at 60 deg C /140 F]
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 20000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

## Drawings

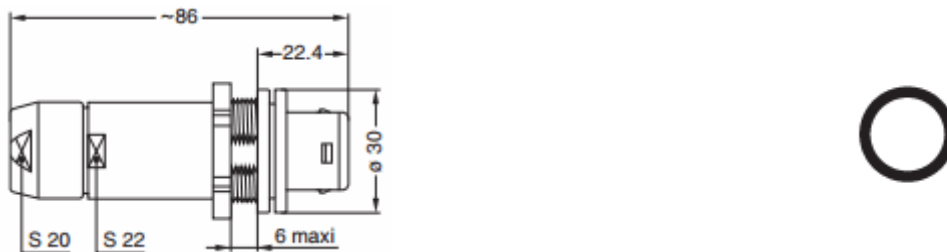

## Dimensions

	<b>A</b>	<b>E</b>	<b>L</b>	<b>M</b>	<b>S1</b>	<b>S2</b>	<b>e</b>
mm.	30	6	86	22.4	22	20	M25x1.0
in.	1.18	0.24	3.39	0.88	0.87	0.79	

[https://www.lemo.com/int\\_en/fez-t7-675-cta01s.html](https://www.lemo.com/int_en/fez-t7-675-cta01s.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.