



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Coax	1
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.80 - 3.10 mm
Size	00
Suggested matching part	<a href="#">PCA.00.250.GTAC29</a>
Series	00 - NIM-CAMAC

[https://www.lemo.com/int\\_en/solutions/specialties/00-nim-camac/ffa-00-250-gtlc29.html](https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/ffa-00-250-gtlc29.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Coax	1
Contact Termination Coax - Conductor fixing	Solder
Contact Termination Coax - Screen fixing	Cable collet
R (max)	6.1 mOhm
Insert configuration value	0.25 - 1 Coax (50 Ohm)
Insulator	T: PTFE
Rated current	4 A
Impedance	50 Ohm
OHM	50
VSWR	$1.09 + 0.11 * f/\text{GHz}$
Vtest	2100 V (AC), 3000 V (DC)
Test voltage	2.1 kV (rms)
Cable type	RG 316 /U
Bucket Dia.	0.6 mm (0.024in)
Contact Dia.	0.7 mm (0.028in)

## Form & Material

Shell style / Model id	FFA - Straight plug with cable collet
Plug	Straight
Housing material	PEEK (Polyetheretherketone) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, female

## Environment

Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-50°C / +250°C (max. temperature valid for short periods of use.)
F ret (min)	100 N


[https://www.lemo.com/int\\_en/solutions/specialties/00-nim-camac/ffa-00-250-gtlc29.html](https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/ffa-00-250-gtlc29.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.80 - 3.10 mm

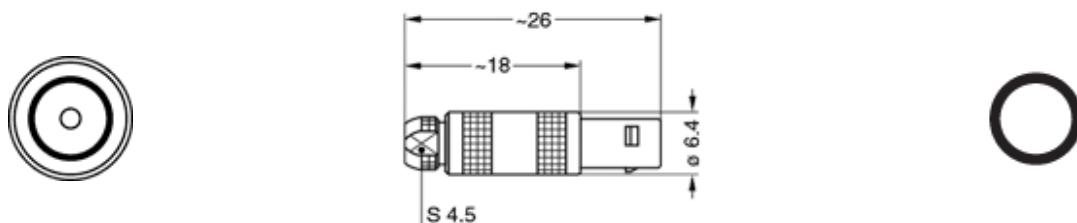

## Drawings



## Dimensions

	A	L	M
mm.	6.4	26	18
in.	0.25	1.02	0.71

## Cables

Cable PartNumber	Material	Colour	Cable image
17420	PVC	Black	
31600	PTFE	Brown	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG1.74AU28N	PVC	Black	
CCX.50.RG3.16U28M	PTFE	Brown	

[https://www.lemo.com/int\\_en/solutions/specialties/00-nim-camac/ffa-00-250-gt1c29.html](https://www.lemo.com/int_en/solutions/specialties/00-nim-camac/ffa-00-250-gt1c29.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.