



## Summary

[Request a quote](#)

[Catalog](#)

|                |                 |
|----------------|-----------------|
| Coax           | 1               |
| Plug           | Plug - Straight |
| Locking system | Push-pull       |
| Size           | 0A              |

## Technical details

### Electrical Configuration

|                            |                          |
|----------------------------|--------------------------|
| Coax                       | 1                        |
| Contact Termination Coax   | Solder                   |
| Insert configuration value | 0A.275 - 1 Coax (75 Ohm) |
| Contact Type               | Coaxial 75 Ohm (Solder)  |
| Bucket Dia.                | 0.65                     |

### Form & Material

|                        |   |
|------------------------|---|
| Shell style / Model id | FFA - Straight plug with cable collet   |
| Plug                   | Straight  |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, gold plated [ISO 27874] latch (plug) or gold earthing crown (receptacle) |
| Locking system         | Push-pull   |
| Keying                 | 3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)   |
| Weight                 | 9.45 g  |

[https://www.lemo.com/int\\_en/ffa-0a-275-ftak66.html](https://www.lemo.com/int_en/ffa-0a-275-ftak66.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Environment

Environmental protection (IP rating)

IP50

## Cable fixation


Cable termination protection

Standard back nut (no additional protection)

Fixation type

Cable collet

# Drawings

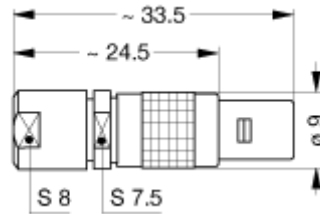

## Dimensions

|     | <b>A</b> | <b>L</b> | <b>M</b> | <b>S2</b> | <b>S1</b> |
|-----|----------|----------|----------|-----------|-----------|
| mm. | 9        | 33.5     | 24.5     | 8         | 7.5       |
| in. | 0.35     | 1.32     | 0.96     | 0.31      | 0.3       |

[https://www.lemo.com/int\\_en/ffa-0a-275-ftak66.html](https://www.lemo.com/int_en/ffa-0a-275-ftak66.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.