



## Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Wire Size/AWG	30 - 22
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.60 - 5.00 mm
Size	0E
Matching parts	<a href="#">ERA.0E.302.CLJ</a>
Alternative part	<a href="#">FFA.0E.302.CLJK50</a>
Series	E - Outdoor Stepped Insert

## Technical details

### Electrical Configuration

Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	0E.302/ThC - 1 Thermocouple Pair
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 Amps
ThC. Materials (P+/N-)	Iron (magnetic) / Constantan
Contact Dia.	0.9
Wire Size/AWG	30 - 22

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Weight	11.64 g

## Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	4.60 - 5.00 mm

# Drawings

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

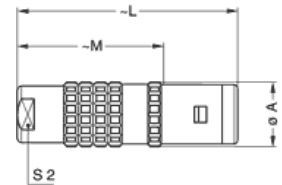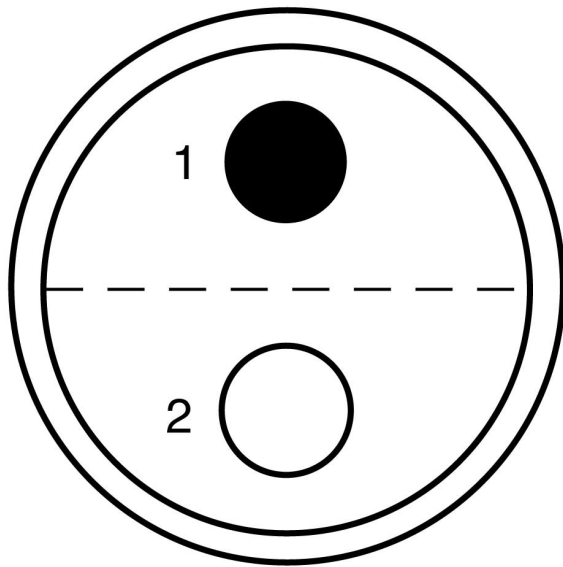

Contact 1: Konstantan (-)  
Contact 2: Iron (+)

### Dimensions

	<b>S2</b>	<b>M</b>	<b>A</b>	<b>L</b>
mm.	8	23	11	34
in.	0.31	0.91	0.43	1.34

[https://www.lemo.com/int\\_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html](https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-cljc50.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.