



Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	2
Wire Size/AWG	30 - 22
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.60 - 4.00 mm
Size	0E
Matching parts	ERA.0E.302.CLK
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	0E.302/ThC - 1 Thermocouple Pair
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 Amps
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	0.9
Wire Size/AWG	30 - 22

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-clkc40z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	12.29 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.60 - 4.00 mm

Drawings

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-clkc40z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

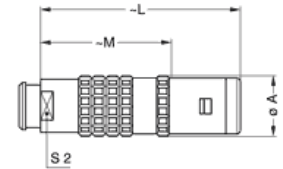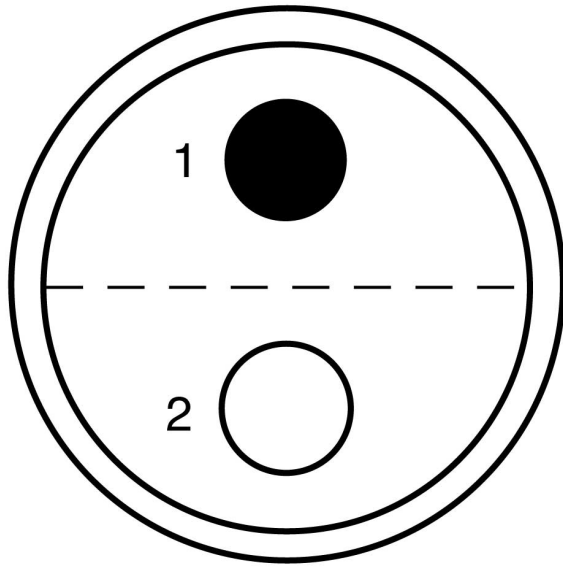

Contact 1: Alumel (-)
 Contact 2: Chromel (+)

Dimensions

	A	S2	M	L
mm.	11	7	23	34
in.	0.43	0.28	0.91	1.34

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-0e-302-clkc40z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.