



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

[Catalog](#)

|                                |                                |
|--------------------------------|--------------------------------|
| Number of contacts Low Voltage | 2                              |
| Wire Size/AWG                  | 30 - 22                        |
| Plug                           | Plug - Straight                |
| Locking system                 | Push-pull                      |
| Size                           | 0S                             |
| Suggested matching part        | <a href="#">ERA.0S.302.CLL</a> |
| Series                         | S - Indoor Stepped Insert      |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

|                                 |                               |
|---------------------------------|-------------------------------|
| Number of contacts Low Voltage  | 2                             |
| Contact Termination Low voltage | Solder                        |
| R (max)                         | 4.8 mOhm                      |
| Insert configuration value      | 0S.302 - 2 Low Voltage        |
| Insulator                       | L: PEEK (UL 94 / V-0/1.5)     |
| Rated current                   | 10 A                          |
| Test voltage (kV DC)            | 1.6                           |
| Max. Solid Conductor            | 0.34 mm <sup>2</sup> (AWG 22) |
| Bucket Dia.                     | 0.8 mm (0.031in)              |
| Contact Dia.                    | 0.9 mm (0.0354in)             |
| Wire Size/AWG                   | 30 - 22                       |

## Form & Material

|                        |   |
|------------------------|---|
| Shell style / Model id | FFA - Straight plug, cable collet   |
| Plug                   | Straight  |
| Housing material       | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Locking system         | Push-pull   |
| Keying                 | Hermaphroditic keying (half moon insert) with male pin 1  |
| Colour                 | Grey  |
| Weight                 | 7.87 g  |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


## Environment

|                                   |   |
|-----------------------------------|---|
| Technical domain                  | Audio Video, Energy and Industrial, Semiconductor, Test and Measurement |
| Environmental sealing (IP rating) | IP50  |
| Endurance                         | 5000 mating cycles  |
| Temperature range                 | -55°C / +250°C (max. temperature valid for short periods of use.)       |
| Climatical Category               | 50/175/21   |
| Humidity (max)                    | <=95% [at 60 deg C /140 F]  |
| Shielding (min)                   | 75 dB (10 MHz)  |
| Shielding (min)                   | 40 dB (1 GHz)   |
| Shock Resistance                  | 100 g [ 6 ms]   |
| Vibration                         | 15 g [10 Hz - 2000 Hz]  |
| Salt Spray Corrosion              | >1000 hr  |

## Cable fixation

|                              |  |
|------------------------------|--|
| Cable termination protection | Standard back nut (no additional protection) |
| Fixation type                | Cable collet                                 |

## Drawings

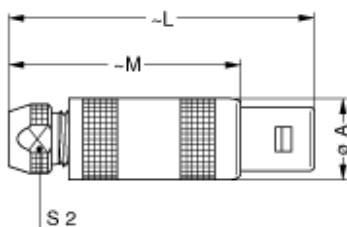

## Dimensions

|     | L    | A    | S2   | M    |
|-----|------|------|------|------|
| mm. | 34.5 | 9    | 6.5  | 24.5 |
| in. | 1.36 | 0.35 | 0.26 | 0.96 |

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Recommended By Lemo

## Accessories

---

Compatible cap

[BFG.0B.100.PCZG](#)

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-302-claa30.html)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.