



## Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Wire Size/AWG	32 - 24
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.30 - 3.20 mm
Size	0S
Matching parts	<a href="#">ERA.0S.303.CLL</a>
Series	S - Indoor Stepped Insert

## Technical details

### Electrical Configuration

Insert configuration value	0S.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	7 Amps
Contact Type	Special
Contact Dia.	0.7
Number of contacts Low Voltage	3
Wire Size/AWG	32 - 24

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	FFA - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Variant	Nut for fitting a bend relief
Weight	8.34 g

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.30 - 3.20 mm

# Drawings

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

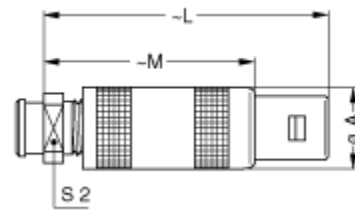

## Dimensions

	<b>L</b>	<b>M</b>	<b>S2</b>	<b>A</b>
mm.	34.5	24.5	7	9
in.	1.36	0.96	0.28	0.35

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-0s-303-clyc27z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.