



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.60 - 3.00 mm
Size	1E
Suggested matching part	PCA.1E.692.CTLC30
Series	E - Outdoor Stepped Insert

Technical details

Electrical Configuration

Insulator	L: PEEK (UL 94 / V-0/1.5)
-----------	---------------------------

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	Circular, male
Colour	Grey
Weight	23.55 g

Environment

Technical domain	Energy and Industrial, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C (max. temperature valid for short periods of use.)
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr


Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.60 - 3.00 mm

https://www.lemo.com/int_en/solutions/originals/e-outdoor-stepped-insert/ffa-1e-692-clac30.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Drawings

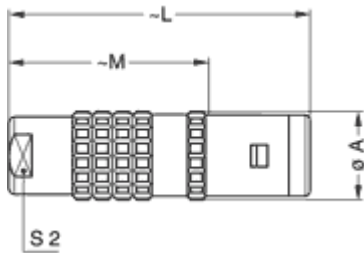

Dimensions

	A	L	M	S2
mm.	13	42	28	9
in.	0.51	1.65	1.1	0.35

Recommended By Lemo

Accessories

Compatible cap	BFA.1E.100.NAS
----------------	--------------------------------