



Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	2
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	2.20 - 3.20 mm
Size	1S
Matching parts	ERA.1S.302.CLJ
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Nb of contacts Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	1S.302/ThC - 1 Thermocouple Pair
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	15 Amps
ThC. Materials (P+/N-)	Iron (magnetic) / Constantan
Contact Dia.	1.3
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-cljc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	2.20 - 3.20 mm

Drawings

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-cljc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

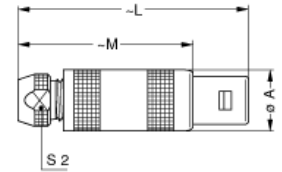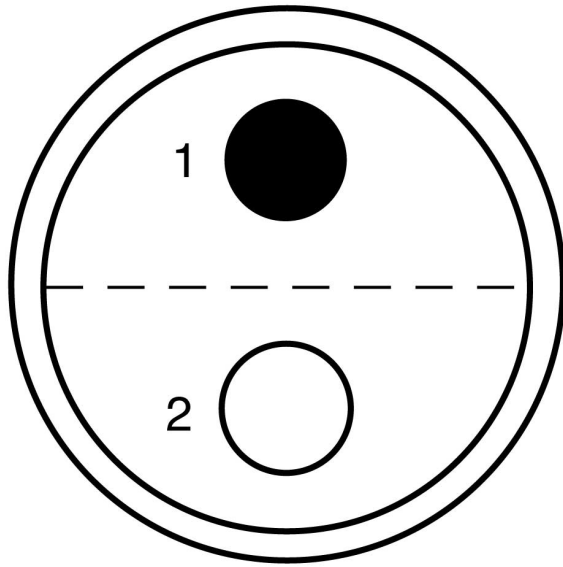

Contact 1: Konstantan (-)
Contact 2: Iron (+)

Dimensions

	L	M	S2	A
mm.	42.5	31.5	8.5	12
in.	1.67	1.24	0.33	0.47

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-cljc32.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.