

Special



*Image for illustrative purpose only*

## Summary

[Request a quote](#)

thermocouple

Nb of contacts Thermocouple	2
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.20 - 4.20 mm
Size	1S
Suggested matching part	<a href="#">ERA.1S.302.CLK</a>
Series	S - Indoor Stepped Insert

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Technical details

## Electrical Configuration

Nb of contacts Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	1S.302/ThC - 1 Thermocouple Pair
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	15 A
ThC. Materials (P+/N-)	Chromel / Alumel
Contact Dia.	1.3
Wire Size/AWG	28 - 20

## Form & Material

Shell style / Model id	FFA - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Colour	Grey
Variant	Nut for fitting a bend relief

## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C (max. temperature valid for short periods of use.)
Climatic Category	55/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.20 - 4.20 mm

## Drawings

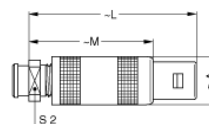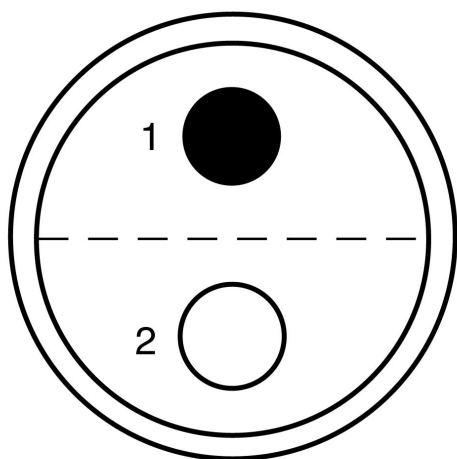

Contact 1: Alumel (-)  
Contact 2: Chromel (+)

## Dimensions

	<b>A</b>	<b>L</b>	<b>M</b>	<b>S2</b>
mm.	12	42.5	31.5	9
in.	0.47	1.67	1.24	0.35

## Recommended By Lemo

### Accessories

Compatible cap

[BFG.1B.100.PCZG](#)

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-302-clkc37z.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.