



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Nb of contacts Thermocouple	2
Number of contacts Low Voltage	1
Wire Size/AWG	30 - 22
Plug	Plug - Straight
Locking system	Push-pull
Size	1S
Suggested matching part	ERA.1S.303.CLL
Series	S - Indoor Stepped Insert

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-303-cltf52z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Nb of contacts Thermocouple	2
Contact Termination Thermocouple	Solder
Insert configuration value	1S.303/ThC - Thermocouple 1 Pair, 1 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
Thermocouple (P+/N-)	Pin 1 / Pin 2
ThC. Materials (P+/N-)	Copper / Constantan
Contact Dia.	0.9
Number of contacts Low Voltage	1
Wire Size/AWG	30 - 22

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	3 keys (alpha=42, gamma=30, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	17.16 g

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-303-cltf52z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr



Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet

Drawings

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-303-cltf52z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

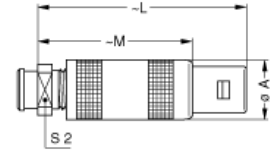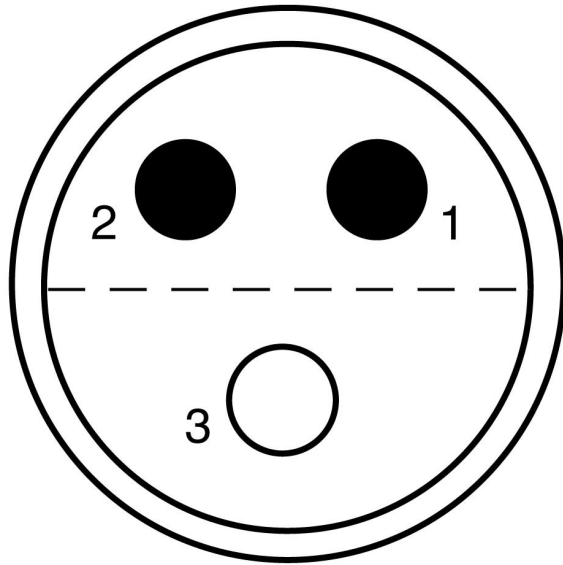

Contact 1: Copper (+)
 Contact 2: Konstantan (-)

Dimensions

	A	L	M	S2
mm.	12	42.5	31.5	9
in.	0.47	1.67	1.24	0.35

Recommended By Lemo

Accessories

Compatible cap

[BFG.1B.100.PCZG](#)

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-1s-303-clt52z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.