



Summary

[Request a quote](#)

[Catalog](#)

Coax	1
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	4.70 - 5.10 mm
Size	2C

Technical details

Electrical Configuration

Coax	1
Contact Termination Coax	Solder
Insert configuration value	2C.250 - 1 Coax (50 Ohm)
Contact Type	Solder

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Circular, male
Weight	16.59 g

https://www.lemo.com/int_en/ffa-2c-250-ctac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Environment

Environmental protection (IP rating)

IP50

Salt Spray Corrosion

>1000 hr

Cable fixation

Cable termination protection

Standard back nut (no additional protection)


Fixation type

Cable collet

Jacket cable outside diameter [mm]

4.70 - 5.10 mm

Drawings

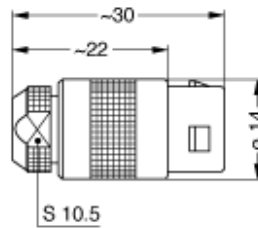

Dimensions

	A	L
mm.	14	30
in.	0.55	1.18

https://www.lemo.com/int_en/ffa-2c-250-ctac52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.