



Summary

[Request a quote](#)

[Catalog](#)

Thermocouple	4
Wire Size/AWG	28 - 20
Plug	Plug - Straight
Locking system	Push-pull
Size	2S
Matching parts	PCA.2S.902.CLLP52
Series	S - Indoor Stepped Insert

Technical details

Electrical Configuration

Thermocouple	4
Insert configuration value	2S.902/ThC - 2 Thermocouple Pairs
Insulator	L: PEEK (UL 94 / V-0/1.5)
Contact Dia.	1.3 mm (0.051" in)
Wire Size/AWG	28 - 20

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-2s-902-cllp52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with female pin 1
Variant	Brazing collet
Weight	33.76 g

Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	20/80/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Pressure	40 bars
Salt Spray Corrosion	>1000 hr


Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet

Drawings

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-2s-902-cllp52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

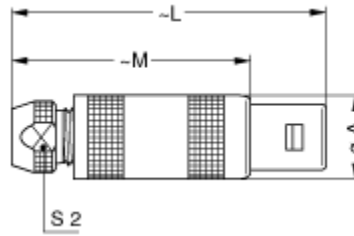

Dimensions

	A	L	M	S2
mm.	14.8	52	40	11
in.	0.58	2.05	1.57	0.43

https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-2s-902-cllp52.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.