



## Summary

[Request a quote](#)

[Catalog](#)

Coax	3
Number of contacts Low Voltage	26
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	13.10 - 14.00 mm
Size	6S
Matching parts	<a href="#">ERA.6S.866.CNL1</a>
Series	S - Indoor Stepped Insert

## Technical details

### Electrical Configuration

Contact Termination Low voltage	Solder
Coax	3
Insulator	N: PBT (discontinued)
Cable type	Cable type: A RG 122 /U S
Number of contacts Low Voltage	26

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Form & Material

Shell style / Model id	FFA - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Weight	624.39 g


## Environment

Technical domain	Audio Video, Energy and Industrial, Semiconductor, Test and Measurement
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [ 6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

## Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	13.10 - 14.00 mm

## Drawings

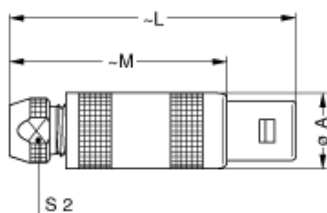

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## Dimensions

	<b>L</b>	<b>M</b>	<b>S2</b>	<b>A</b>
mm.	106	81	38	46
in.	4.17	3.19	1.5	1.81

[https://www.lemo.com/int\\_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html](https://www.lemo.com/int_en/solutions/originals/s-indoor-stepped-insert/ffa-6s-866-cnac144.html)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.